

## RCA Stereo Audio Male /Male cord

Cat. No(s): 0 514 03/04



### 1. USE

#### Cord for video transmission

Straight RCA Stereo Audio - RCA Stereo Audio (cable with multicore cords)

### 2. DESCRIPTION


Don't let your interconnects be the weak link in your audio system chain! This audio cable offers excellent sound quality because its bonded construction design delivers a neat, easy connection of audio signals. Twisted pair oxygen-free copper wire and foamed PE dielectric are optimized for audio signal transmission. The low-loss 100% foil and spiral-wound oxygen-free copper shielding protects the delicate signals from electromagnetic interference (EMI) and radio frequency interference (RFI). Colour-coded snagless connectors and an ultra-flexible jacket enable easy installation. 24-karat gold-plated heavy duty contacts ensure a lifetime of performance.

Connector 1: (1) RCA Stereo Audio Male  
 Connector 2: (1) RCA Stereo Audio Male

- 100% foil and braid shield protects against noise and interference
- Twisted-pair construction of audio conductors fight noise and hum
- Colour-coded snagless connectors and an ultra-flexible jacket allow for easy installation

### 3. DIMENSIONS

Cat. Nos	Length (m)
0 514 03	2
0 514 04	5

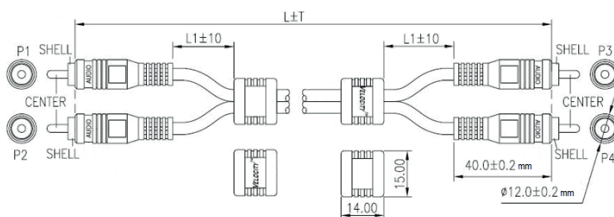


Connector 1 : RCA Stereo Audio Male  
 Connector 2 : RCA Stereo Audio Male  
 L : 2000/5000mm  
 T : +152 / -51mm  
 L1 : 200mm

### 4. PHYSICAL CHARACTERISTICS

Approvals	RoHS compliant
-----------	----------------

#### Cable :

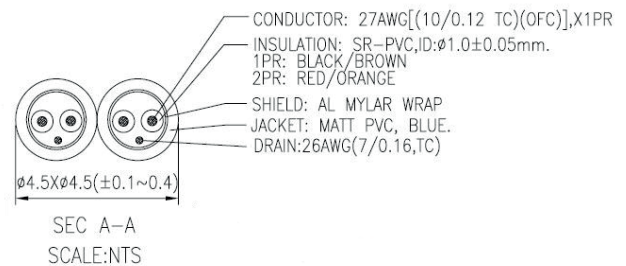

#### Connector :

P1 ~ P4: RCA plug solder type, gold flash and shell  
 All hood : molded black.