 
 


0 380 97

 


1 380 93




10T55

1 380 94




1 380 95

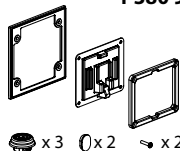


• x3 ○ x2 ↗ x2





0 380 97

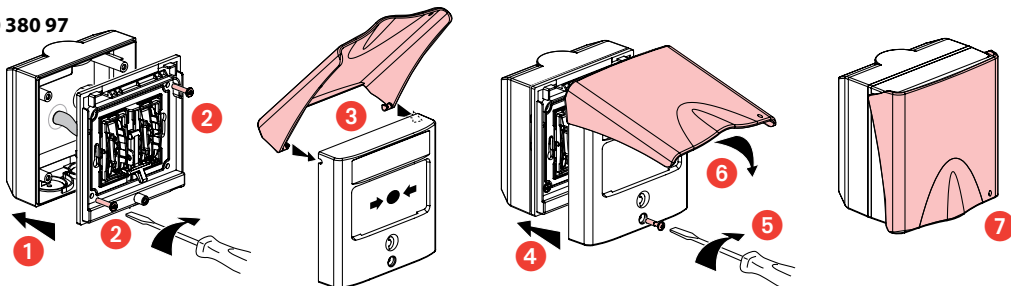

0 380 97 +



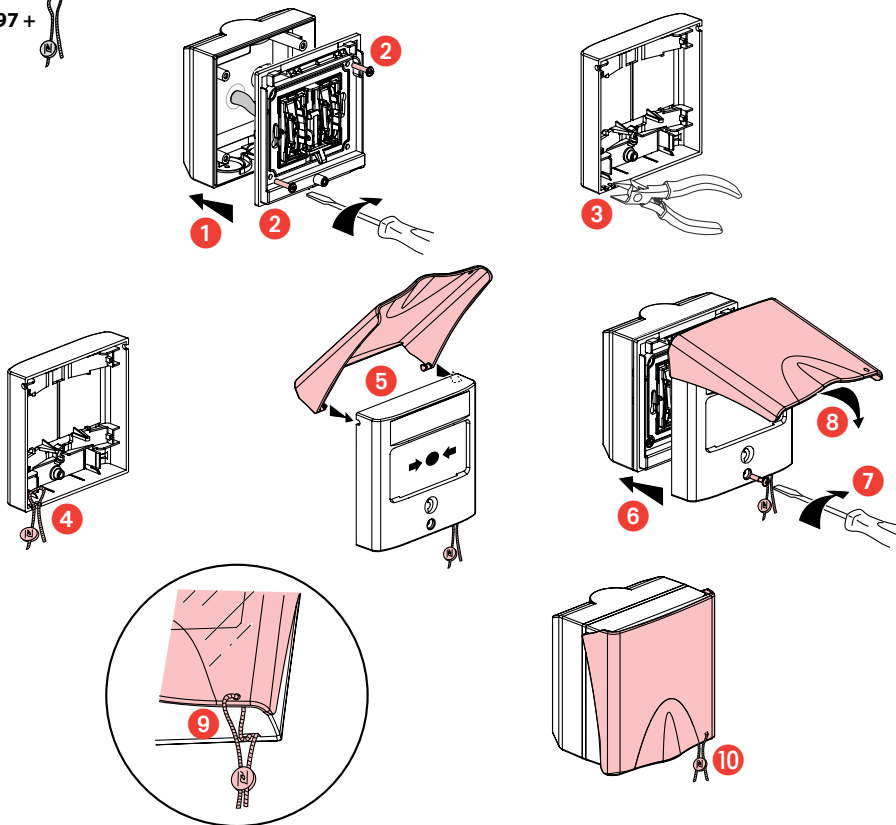


1 380 93

 
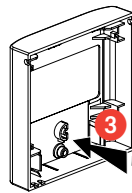
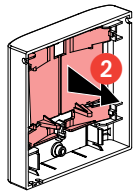
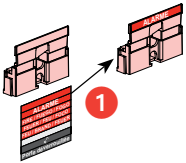


10T55

- +55°C
- -10°C



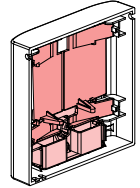
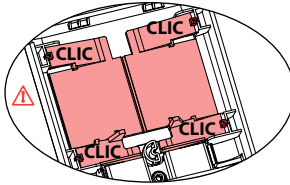
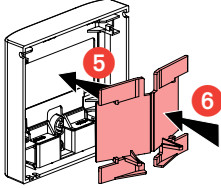


1 380 94

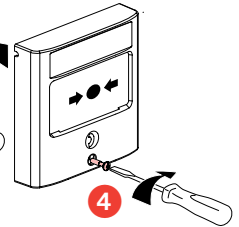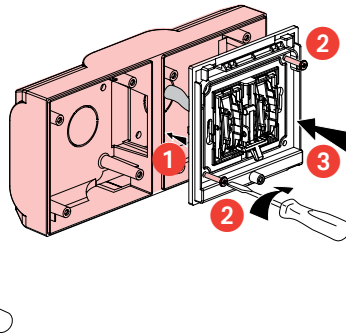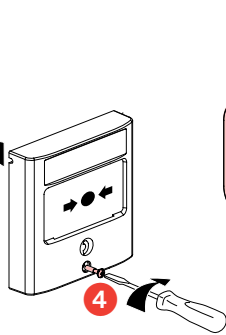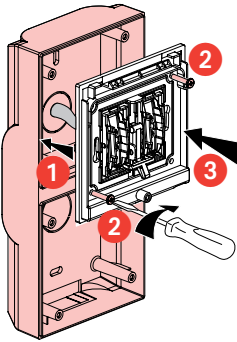

1 380 95

/ NF EN 60669-1 : 

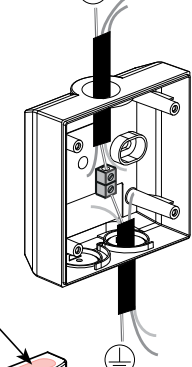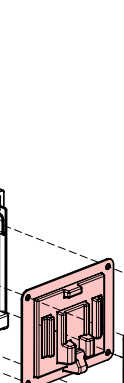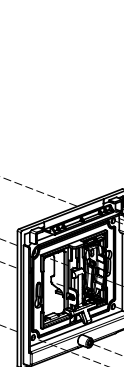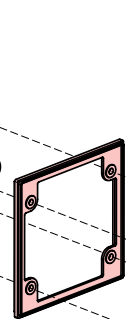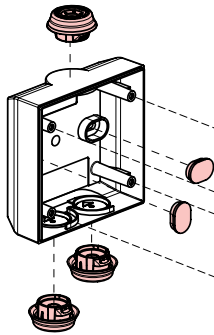

0,5 Nm <  < 0,8 Nm

IP65